



# vulcan<sup>®</sup> 714 Master


## Key performance

- Long blanket lifetime
- High print quality
- Calibrated thickness
- Positive paper feed

## MAIN APPLICATION

Heatset

**Vulcan 714 Master is available in 3-ply, 1,71 mm thickness**

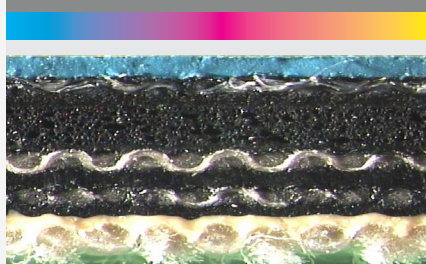

**714 Master**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	Conventional
<b>PRINTING SURFACE COLOUR</b>	Light Blue
<b>THICKNESS (mm)</b>	1,71
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	235
<b>SURFACE ROUGHNESS (Ra micron)</b>	1,0
<b>FEED FEATURES</b>	Positive
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTH (N/mm)</b>	>75
<b>WATER &amp; SOLVENT PROTECTION</b>	Yes
<b>ADDITIONAL INFORMATION</b>	
<b>BLANKET CONSTRUCTION</b>	High speed web presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**