

# vulcan® 714 Master


## Key performance

- Long blanket lifetime
- High print quality
- Calibrated thickness
- Positive paper feed

## MAIN APPLICATION

Newspaper Coldset

**Vulcan 714 Master is available  
in 4-ply, 1,96 mm thickness**

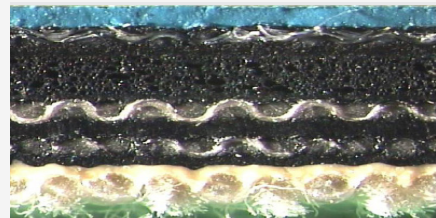

**Vulcan 714 Master**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	Conventional
<b>PRINTING SURFACE COLOUR</b>	Light Blue
<b>THICKNESS (mm)</b>	1,96
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	235
<b>SURFACE ROUGHNESS (Ra micron)</b>	1,0
<b>FEED FEATURES</b>	Positive
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTHS (N/mm)</b>	>70
<b>WATER &amp; SOLVENT PROTECTION</b>	Yes
<b>ADDITIONAL INFORMATION</b>	
<b>BLANKET CONSTRUCTION</b>	The micro ground surface combined with a robust carcass construction results in a calibrated blanket tickness with a minimal relevance.

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**