



# vulcan® UV


## Key performance

- Specifically designed for UV applications
- Increased blanket lifetime
- Reduced downtime due to less blanket changes
- Sticky back blanket is available for business forms and labels printing

## MAIN APPLICATION

UV

**Vulcan UV is available in 3 ply, 1,70 - 1,95 mm thickness.**

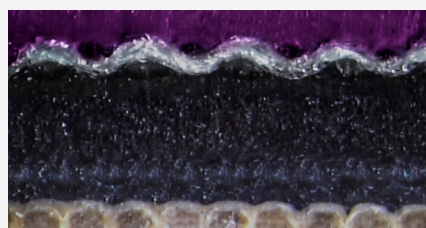

Vulcan UV

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	UV
<b>PRINTING SURFACE COLOUR</b>	Purple
<b>THICKNESS (mm)</b>	1,70 / 1,95
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	300
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTHS (N/mm)</b>	>60
<b>WATER &amp; SOLVENT PROTECTION</b>	N/A
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Adhesive on Request

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**