




Key performance

- High mechanical resistance
- Designed with **Feed-0 Technology**:
 - Optimum paper feed tension
 - Reduced risks of paper breaks
 - Easier control of colour register during the start-up
 - Improved paper wastage control

MAIN APPLICATION

Newspaper Coldset

Vulcan 202 is available in 4-ply, 1,96 mm thickness

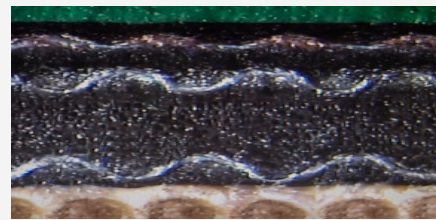

Vulcan 202

✓ The product at a glance

| | |
|--|----------------------------------|
| INK COMPATIBILITY | Hybrid |
| THICKNESS (mm) | 1.96 |
| PRINTING SURFACE COLOUR | Green |
| AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation | 250 |
| SURFACE ROUGHNESS (Ra micron) | 1,0 |
| FEED FEATURES | Neutral |
| ELONGATION (%) | <0,9 |
| TENSILE STRENGTHS (N/mm) | >75 |
| WATER & SOLVENT PROTECTION | Yes |
| ADDITIONAL INFORMATION | |
| ADVANCED TECHNOLOGY | FEED-0 no pack version available |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**