

# vulcan® Editor 10


## Key performance

- Neutral paper feed
- Implements all benefits of the **Dynatech System:** better vibration absorption, less gears streaking marks, higher paper smash resistance, blanket consistency and excellent reboundability
- Designed with **Feed-0 Technology:**
  - Optimum paper feed tension
  - Reduced risks of paper breaks
  - Easier control of colour register during the start-up
  - Improved paper wastage control

## MAIN APPLICATION

Newspaper Coldset

**Vulcan Editor 10 is available in 3 ply, 1,95 mm thickness.**

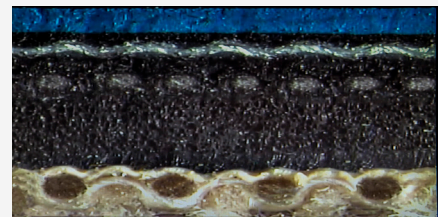

**Vulcan Editor 10**



## The product at a glance

<b>INK COMPATIBILITY</b>	Hybrid
<b>PRINTING SURFACE COLOUR</b>	Blue
<b>THICKNESS (mm)</b>	1,95
<b>AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation</b>	250
<b>SURFACE ROUGHNESS (Ra micron)</b>	1,0
<b>FEED FEATURES</b>	Neutral
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTHS (N/mm)</b>	>60
<b>WATER &amp; SOLVENT PROTECTION</b>	Yes
<b>NEW TECHNOLOGY</b>	Dynatech and Feed-0
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Suitable for high speed presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**