




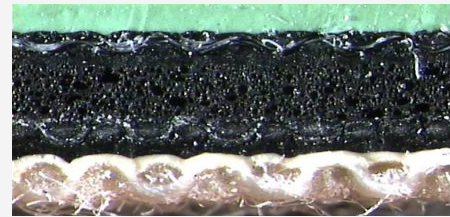
Key performance

- Specifically designed for wide format web heatset presses
- Slightly positive paper feed
- Very good stability and versatility
- Long blanket lifetime
- High print quality


MAIN APPLICATION

Heatset

Vulcan Alto Plus is available in 3/4-ply, 1,70/1,95 mm thickness.

Vulcan Alto Plus

 **The product at a glance**

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Light Green
THICKNESS (mm)	1,70/1,95
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
FEED FEATURES	Slightly Positive
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
PRESS FORMAT	The most successful blanket for wide format web heatset presses

FOR ANY FURTHER DETAILS AND FOR A QUOTATION PLEASE REFER TO YOUR SALES MANAGER OR EMAIL US AT: printingsm@trelleborg.com