




## Key performance

- Specifically designed to absorb the mechanical vibrations caused by new generation printing presses
- Implements all benefits of the **Dynatech System**:
  - Better vibration absorption
  - Less gears streaking marks
  - Higher paper smash resistance
  - Blanket consistency
  - Excellent reboundability

## MAIN APPLICATION

Heatset

Vulcan Techno is available in 3 ply, 1,70 mm thickness

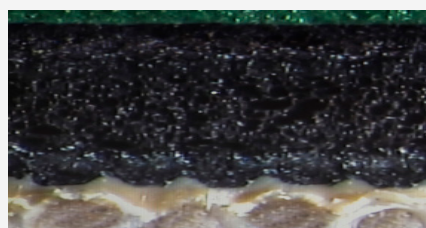

Vulcan Techno

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	Hybrid
<b>PRINTING SURFACE COLOUR</b>	Green
<b>THICKNESS (mm)</b>	1,70
<b>AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation</b>	250
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>FEED FEATURES</b>	Positive
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTH (N/mm)</b>	>60
<b>WATER &amp; SOLVENT PROTECTION</b>	Yes
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Perfect choice for 16pp

FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)