

Intaglio




Key performance

- Non compressible blanket for intaglio applications
- Surface able to allow a proper foil release and excellent ink transfer even at low pressure
- High temperature resistance over 100°C

MAIN APPLICATION

Security Printing

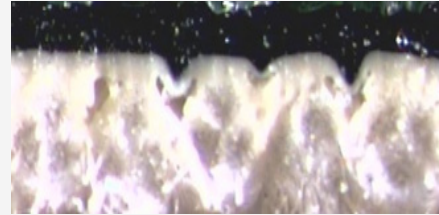

Intaglio

Intaglio is available in 1-ply, 0,50 mm thickness

✓ The product at a glance

INK COMPATIBILITY	Conventional
THICKNESS (mm)	0,50 +0,04/-0,03
PRINTING SURFACE COLOUR	Black
TABER ABRASION (WEIGHT 500g, WHEEL H22, 500 CYCLES)	≤7%
ELONGATION (% , WARP/WEFT)	≤8/≤20
TENSILE STRENGTH (N/5 cm, WARP/WEFT)	≥1400/≥250
ADDITIONAL INFORMATION	
APPLICATIONS	Printing of banknotes, checks, passports, visa

FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com