



Intaglio





Key performance

- Non compressible blanket for intaglio applications
- Surface able to allow a proper foil release and excellent ink transfer even at low pressure
- High temperature resistance over 100° C

MAIN APPLICATION

Security Printing

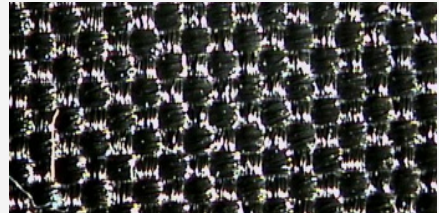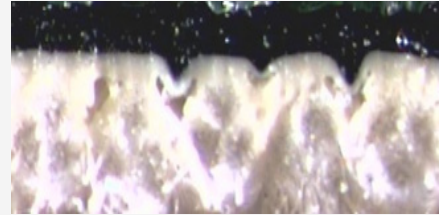

Intaglio

Intaglio is available in 1-ply, 0,50 mm thickness

✓ The product at a glance

INK COMPATIBILITY	Conventional
THICKNESS (mm)	0,50 +0,04/-0,03
PRINTING SURFACE COLOUR	Black
TABER ABRASION	≤1,5%
ELONGATION (% , MD/CD)	≤5/≤35
TENSILE STRENGTH (N/5 cm, MD/CD)	≥2100/≥950
ADDITIONAL INFORMATION	
APPLICATIONS	Printing of banknotes, checks, passports, visa

FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com