

# vulcan<sup>®</sup> DUO


## Key performance

- Unique blanket design
- Improved Smash resistance and high durability
- Reduced edge mark
- Very flexible for an easy mounting on press
- Suitable for hybrid printing
- Dedicated for packaging and commercial sheetfed

## MAIN APPLICATION

Commercial Sheetfed,  
Packaging

**Vulcan DUO is available in 2-ply,  
1,96 mm thickness.**

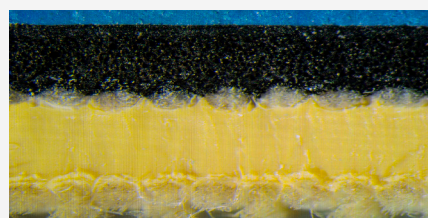

**Vulcan Duo**



## The product at a glance

|                                                                      |                                   |
|----------------------------------------------------------------------|-----------------------------------|
| <b>INK COMPATIBILITY</b>                                             | Hybrid                            |
| <b>THICKNESS (mm)</b>                                                | 1.96                              |
| <b>PRINTING SURFACE COLOUR</b>                                       | Blue                              |
| <b>AVERAGE LOAD VALUE<br/>N/cm<sup>2</sup> @ 0,23 mm Indentation</b> | 250                               |
| <b>SURFACE ROUGHNESS<br/>(Ra micron)</b>                             | 0,8                               |
| <b>ELONGATION (%)</b>                                                | <1,1                              |
| <b>TENSILE STRENGTHS (N/mm)</b>                                      | >140                              |
| <b>ADDITIONAL INFORMATION</b>                                        |                                   |
| <b>APPLICATIONS</b>                                                  | Commercial Sheetfed and Packaging |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**