




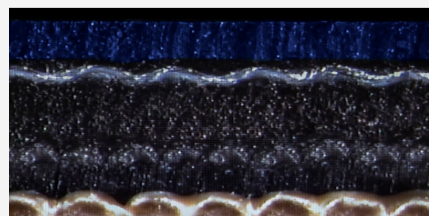
Key performance

- Very good half tone reproduction and overall printing quality
- Proper shock mark absorption
- Excellent paper smash resistance
- Reliable commercial sheetfed performer

MAIN APPLICATION

Sheetfed Commercial & Packaging

Vulcan Easy Plus is available in 3 ply, 1,96 mm thickness

Vulcan Easy Plus

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,2
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>59
ADDITIONAL INFORMATION	
APPLICATIONS	All-round sheetfed blanket

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**