

Pack


Key performance

- Ideal for 4-color presses
- Excellent half tone reproduction and ink transfer coverage
- High edge marking resistance
- Increased blanket lifetime

MAIN APPLICATION

Metal decorating

**Vulcan Pack is available in
3-ply, 1,96 mm thickness**

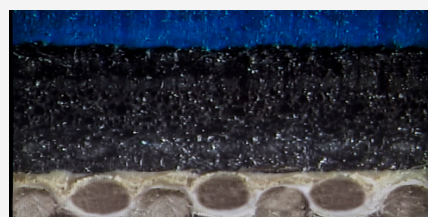

Vulcan Pack



The product at a glance

INK COMPATIBILITY	Hybrid
THICKNESS (mm)	1.96
PRINTING SURFACE COLOUR	Blue
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	400
SURFACE ROUGHNESS (Ra micron)	1,3
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>67
ADDITIONAL INFORMATION	
APPLICATIONS	Commercial Sheetfed and Packaging

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**