



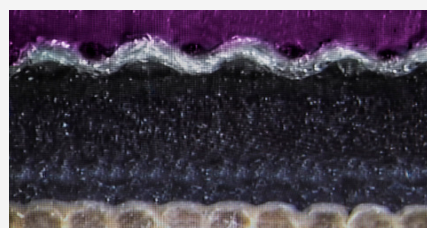

Key performance

- Specifically designed for UV applications
- Increased blanket lifetime
- Reduced downtime due to less blanket changes
- Sticky back blanket is available for business forms and labels printing

MAIN APPLICATION

Sheetfed

**Vulcan UV is available in
3 ply, 1,71 - 1,96 mm thickness**



Vulcan UV



The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	1,71 / 1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	260
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>60
ADDITIONAL INFORMATION	
MORE VERSIONS	Adhesive on request

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**