




Key performance

- Specifically designed for UV inks
- Excellent half tone reproduction
- Reduced gauge loss
- Implements all benefits of the **Dynatech System**:
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

UV

Vulcan Folio UV is available in 3 ply, 1,96 mm thickness

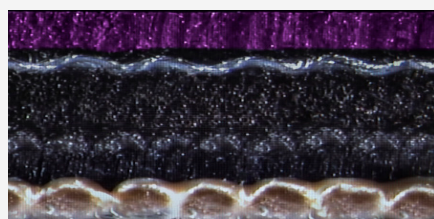

Vulcan Folio UV



The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	260
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>60
ADVANCED TECHNOLOGY	Dynatech
ADDITIONAL INFORMATION	
APPLICATIONS	Top Quality Printing

FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com