



# vulcan® Sunrise

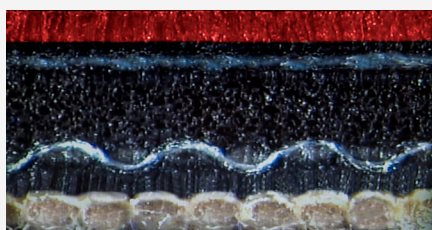
## Key performance

- Specifically designed for the latest UV applications (LE/HUV, LED UV)
- Excellent printing quality (solids and half tone reproduction)
- Very good ink release
- Avoid ink back-trapping
- Implements all benefits of the **Dynatech System:**
  - Excellent smash and edge marks resistance
  - Better vibration absorption

## MAIN APPLICATION

UV

**Vulcan Sunrise is available in 3 ply, 1,96 mm thickness.**

**Vulcan Sunrise**

## ✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Red
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm <sup>2</sup> @ 0,23 mm Indentation	230
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
<b>ADDITIONAL INFORMATION</b>	
APPLICATIONS	Dynatech System

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**