



# vulcan<sup>®</sup> Super UV


## Key performance

- Ideal for packaging multi-color solid printing, UV inks
- Excellent half tone reproduction and ink transfer coverage
- High edge marking resistance
- Increased blanket lifetime

## MAIN APPLICATION

UV

**Vulcan Super UV is available in 3 ply, 1,96 mm thickness.**

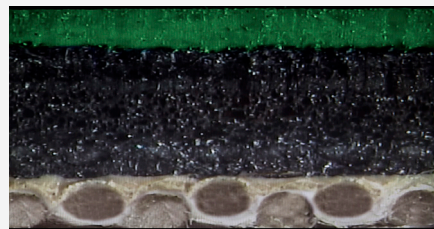

**Vulcan Super UV**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	UV
<b>PRINTING SURFACE COLOUR</b>	Green
<b>THICKNESS (mm)</b>	1,96
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	400
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTHS (N/mm)</b>	>60
<b>WATER &amp; SOLVENT PROTECTION</b>	No
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Specifically designed for metal decorating applications

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**