




## Key performance

- New thicker compressible layer to further enhance Feed-0 technology benefits
  - Optimum paper feed tension: control on reverse piling and paper release, reduced paper wastages and breaks
  - Easier control of color register during the start-up
- New top compound: exceptional ghosting resistance and optimum print quality
- Advanced design to boost product lifetime

## MAIN APPLICATION

### Heatset

**Vulcan Mytho Evo is available in 3 ply, 1,70 mm thickness**

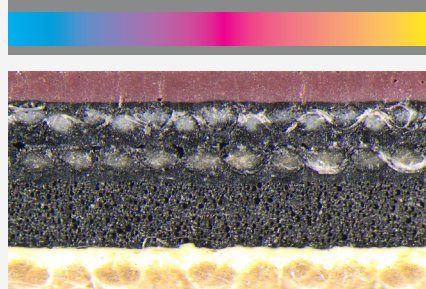

**Vulcan Mytho Evo**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	Hybrid
<b>PRINTING SURFACE COLOUR</b>	Amaranth
<b>THICKNESS (mm)</b>	1,70
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	250
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>FEED FEATURES</b>	Neutral
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTH (N/mm)</b>	>60
<b>WATER &amp; SOLVENT PROTECTION</b>	Yes
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATION</b>	Excellent choice for wide format web heatset presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**