

vulcan® Event


Key performance

- A 3 ply blanket with microsphere
- Good smash resistance on a variety of stocks
- Excellent mechanical resistance
- Very good half tone reproduction and overall printing quality
- Implement all benefits of the **Dynatech System**

MAIN APPLICATION

Commercial Sheetfed

Vulcan Event is available in 3-ply,
1,95 mm thickness

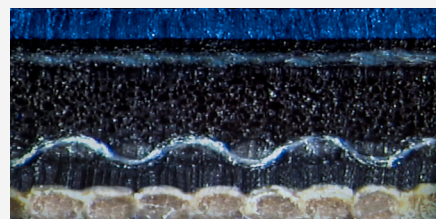

Vulcan Event

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	245
SURFACE ROUGHNESS (Ra micron)	1,0
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>67
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
SPECIAL COMPRESSIBLE LAYER	Excellent reboundability characteristic to provide a good ink transfer during printing

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printing@trelleborg.com**