



vulcan[®] 714 Master


Key performance

- Long blanket lifetime
- High print quality
- Calibrated thickness
- Positive paper feed

MAIN APPLICATION

Newspaper Coldset, Hetaset
Sheetfed, Packaging

Vulcan 714 Master is available in 4-ply, 1,70 - 1,96 mm thickness.

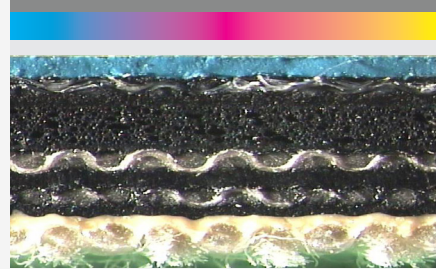

714 Master



The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Light Blue
THICKNESS (mm)	1,70 - 1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	240
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Positive
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
BLANKET CONSTRUCTION	The micro ground surface combined with a robust carcass construction results in a calibrated blanket thickness with a minimal relevance.

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**