

vulcan® Editor 10 No Pak


Key performance

- Neutral paper feed
- Implements all benefits of the **Dynatech System:** better vibration absorption, less gears streaking marks, higher paper smash resistance, blanket consistency and excellent reboundability
- Designed with **Feed-0 Technology:**
 - Optimum paper feed tension Reduced risks of paper breaks
 - Easier control of colour register during the start-up
 - Improved paper wastage control

MAIN APPLICATION

Heatset, Coldset

Vulcan Editor 10 No Pak is available in 3 ply, 2,06 - 2,08 mm thickness.

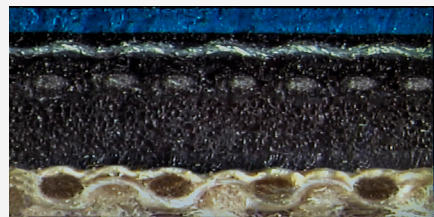

Vulcan Editor 10 No Pak



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	2,06 - 2,08
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Neutral
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
NEW TECHNOLOGY	Dynatech and Feed-0
ADDITIONAL INFORMATION	
APPLICATIONS	Suitable for high speed presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**