

Rollin® UVI

TRELLEBORG


使用用途

- UV印刷用
(枚葉、厚紙、フィルム印刷)

特徴

- ベタの着肉性に優れる。
- インキ転移性に優れ、紙離れも良好。
- 水無しUV印刷にも対応。


断面図

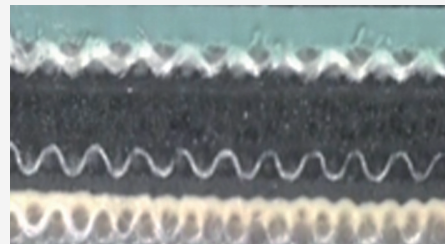

仕様

- | | | | |
|-------------|-------------------|------------------|---------------------|
| • 表面ゴム色 | : 深緑色 | • インキ適合性 | : UV専用 |
| • 表面粗度 (Ra) | : 0.5~1.0 μ m | • 全体硬度 (shore A) | : 74° |
| • 公称厚み | : 1.95mm | • 実測厚み | : 1.96 $\pm$ 0.02mm |

(特性レーダーチャート)

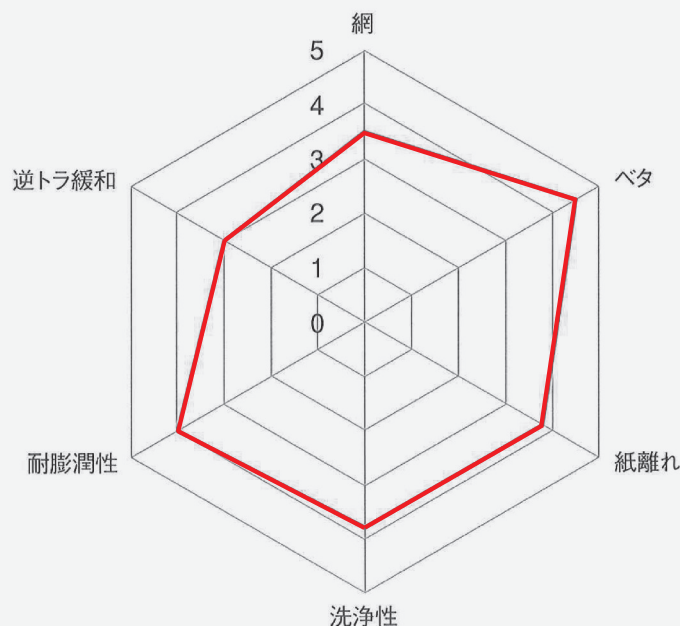

www.trelleborg.com/printing

The information contained in this document is intended to provide guidance. The information is NOT a specification and all figures in the document are nominal. This document and the information it contains do not create any warranties for any product and Trelleborg Printing Solutions disclaims any warranty of merchantability or fitness for a particular purpose for the product described in this document. This document discloses information that is proprietary to Trelleborg Printing Solutions. The receipt or possession of the document does not confer any right to reproduce or disclose the document, any information contained in it, or any physical article or device, or to practice any method or process except by written agreement with Trelleborg Printing Solutions. Trelleborg Printing Solutions is committed to the ongoing development of its products. For that reason, Trelleborg Printing Solutions reserves the right to alter the actual specifications of its products without prior notice.



WWW.TRELLEBORG.COM/PRINTING

For more information:

Visit us: www.trelleborg.com/printing

Email us: printing@trelleborg.com

Twitter: twitter.com/PrintingInsight

YouTube: youtube.com/user/PrintingInsights

日本トレルボルグシーリングソリューションズ株式会社
プリンティングブランケット事業部
〒213-0012 神奈川県川崎市高津区坂戸3-2-1 KSP 204号
TEL : 044-850-3010 FAX : 044-850-3012