


Type R


Durable & stable thin sleeve

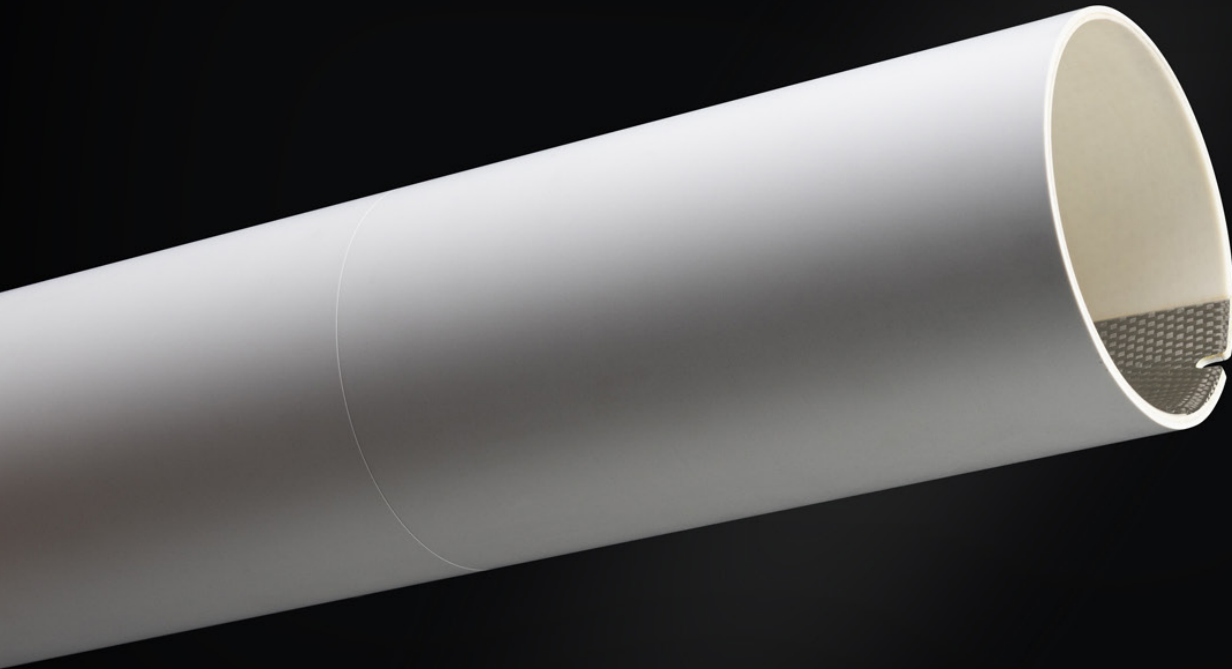

Type R

features and benefits:

1. Light and stable structure for consistent print results & easy handling.
2. Durable register slots, to keep precise registration over time.
3. Smooth installation on press & quick make ready.

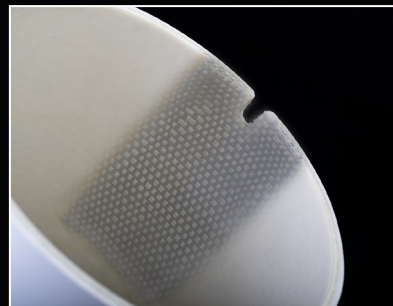

Durable & precise registration using Carbon fibre



Easy positioning of adhesives and plates thanks to scribe lines

Technical data

Application	Hard pneumatic plate mounting sleeve
Ink system	Compatible with all Flexo inks (solvent based, water based and UV)
Tapes	Compatible with all market tapes used in plate mounting
Tolerance on Outer Diameter	Nominal +/- 20µm
Tolerance on TIR	20µm
Surface	Extremely durable Epoxy & technical fabrics
Utilisation Temperature range	20°C to 45°C
Wall thickness range	From 0.3 to 4.999mm
Width range	From 200 to 2000mm
Stork Diameter range	From 60 to 400mm
Conductive	Fulfill ATEX 95 requirements when required
Air supply	6 bars @ minimum 12l/sec
Cleaning	Any solvent compatible with UV, solvent and water based inks
Storage	Vertical / Horizontal indifferent

The logo for Axcyl, featuring the word "Axcyl" in a bold, italicized sans-serif font. The letter 'x' is stylized with a horizontal bar that is split into yellow, pink, and blue segments.The logo for Trelleborg, consisting of a stylized 'T' and 'W' symbol above the word "TRELLEBORG" in a bold, uppercase sans-serif font.

Trelleborg Printing Solutions is a leading global manufacturer and supplier of unique printing solutions for offset, flexo and digital applications.

Trelleborg Axcyl plate mounting sleeves for narrow and wide web printing presses help flexo printers enhancing and improving performance, in efficient and sustainable way.

WWW.TRELLEBORG.COM/PRINTING

printingsm@trelleborg.com
<https://www.linkedin.com/company/trelleborg-printing-solutions>
<https://twitter.com/PrintingInsight>

