


When it comes to maximize  
your return on investment, think  
**Coaxcyl EM**



**Coaxcyl EM**

features and benefits:


1. Honeycomb based structure, for consistent print results & easy handling
2. Dampening function built-in to reduce press bounce
3. Designed to last long
4. Smooth installation on press & quick make ready

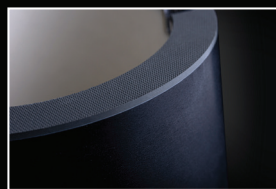

Durable End Cap



Durable & precise registration  
Aluminum insert

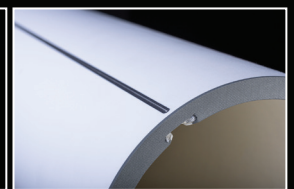

Cutting guide  
Ceramic based

## Technical data

<b>Application</b>	Hard pneumatic plate mounting sleeve
<b>Ink system</b>	Compatible with all Flexo inks (solvent based, water based and UV)
<b>Tapes</b>	Compatible with all market tapes used in plate mounting
<b>Tolerance on Outer Diameter</b>	Nominal +/- 20µm
<b>Tolerance on TIR</b>	20µm
<b>Surface</b>	Extremely durable Epoxy & technical fabrics
<b>Utilisation Temperature range</b>	20°C to 45°C
<b>Wall thickness range</b>	From 4 to 100mm
<b>Width range</b>	From 500 to 2000mm
<b>Stork Diameter range</b>	From 60 to 400mm
<b>Conductive</b>	Fulfill ATEX 95 requirements when required
<b>Air supply</b>	6 bars @ minimum 12l/sec
<b>Cleaning</b>	Any solvent compatible with UV, solvent, and water-based inks
<b>Storage</b>	Vertical / Horizontal indifferent



Trelleborg Printing Solutions is a leading global manufacturer and supplier of unique printing solutions for offset, flexo and digital applications.

Trelleborg Axcyl plate mounting sleeves for narrow and wide web printing presses help flexo printers enhancing and improving performance, in efficient and sustainable way.

[WWW.TRELLEBORG.COM/PRINTING](http://WWW.TRELLEBORG.COM/PRINTING)

[printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)  
<https://www.linkedin.com/company/trelleborg-printing-solutions>  
<https://twitter.com/PrintingInsight>

