




Key performance

- Specifically designed for currency printing
- Perfect solid printing and ink transfer
- Suitable for fine details reproduction
- Very robust carcass to provide stability on press

MAIN APPLICATION

Currency Printing

Printec 788 is available in 3-ply, 1,70 mm tickness

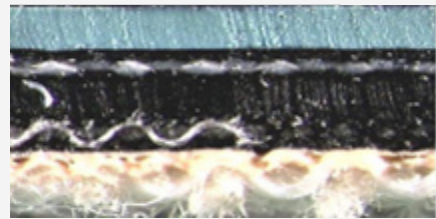

Printec 788

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Light Blue
THICKNESS (mm)	1,70 +/- 0,02
SURFACE ROUGHNESS (Ra micron)	1,25
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	Non compressible blanket
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>150
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
APPLICATIONS	Security printed products

FOR ANY FURTHER DETAILS AND FOR A QUOTATION PLEASE REFER TO YOUR SALES MANAGER OR EMAIL US AT: printingsm@trelleborg.com