



Rollin[®]SEK




Key performance

- Specifically designed for currency printing
- Perfect solid printing and ink transfer
- Suitable for fine details reproduction
- Very robust carcass to provide stability on press

MAIN APPLICATION

Security Printing

**Rollin SEK is available in 3 ply,
1,70 mm tickness**

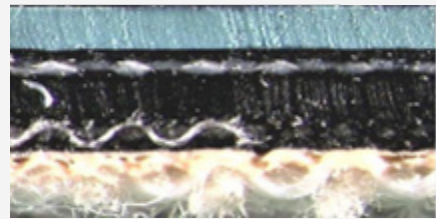

Rollin SEK

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Light blue
THICKNESS (mm)	1,70
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	Non compressible blanket

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**