

# Rollin<sup>®</sup> Intaglio


## Key performance

- Special fabric with extremely strong and low stretch resistance to guarantee stability and longevity on the press
- Surface able to allow a proper foil release and excellent ink transfer even at low mechanical pressure
- High temperature resistance, over 100 °C

## MAIN APPLICATION

Security Printing

**Rollin Intaglio is available in  
1-ply, 0,50 mm thickness**

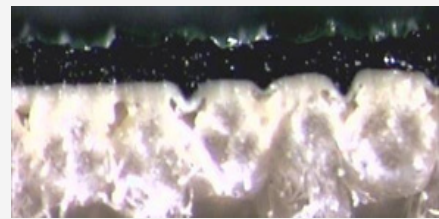

**Rollin Intaglio**



## The product at a glance

<b>INK COMPATIBILITY</b>	N.A.
<b>THICKNESS (mm)</b>	0,50
<b>PRINTING SURFACE COLOUR</b>	Black
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	NA
<b>SURFACE ROUGHNESS (Ra micron)</b>	NA
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Security Printing

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**