

vulcan[®] Royal Form UV


Key performance

- Specifically designed for UV inks
- Sticky back blanket
- High print quality
- High edge marking resistance
- Increased blanket lifetime
- Suitable for labels and envelopes printing
- Adhesive: clean and easy removal from the cylinder

MAIN APPLICATION

Business Forms, Labels

Vulcan Royal Form UV is available in 2 ply, 0,90 - 0,95 - 1,00 - 1,05 mm thickness.

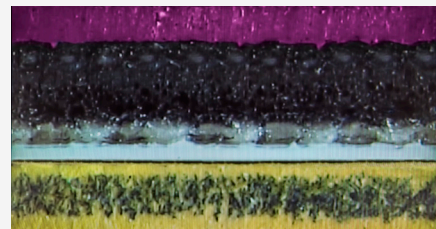

Vulcan Royal Form UV

✓ The product at a glance

| | |
|--|---------------------------|
| INK COMPATIBILITY | UV |
| PRINTING SURFACE COLOUR | Purple |
| THICKNESS (mm) | 0,90 - 0,95 - 1,00 - 1,05 |
| AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation | 300 |
| SURFACE ROUGHNESS (Ra micron) | 0,8 |
| ELONGATION (%) | N/A |
| TENSILE STRENGTHS (N/mm) | N/A |
| WATER & SOLVENT PROTECTION | N/A |
| ADDITIONAL INFORMATION | |
| APPLICATIONS | Dedicated for UV inks |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**