



vulcan® 714 Master


Key performance

- Long blanket lifetime
- High print quality
- Calibrated thickness
- Positive paper feed

MAIN APPLICATION

Newspaper Coldset,
Heatset

**Vulcan 714 Master is available in
4-ply, 1,70 - 1,95 mm thickness.**

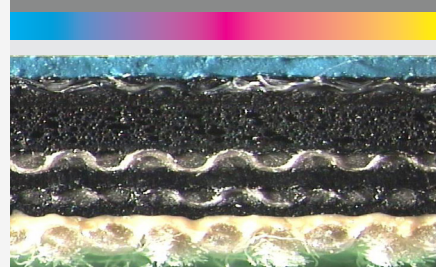

714 Master



The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Light Blue
THICKNESS (mm)	1,70 - 1,95
AVERAGE LOAD VALUE N/cm ² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Positive
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
BLANKET CONSTRUCTION	The micro ground surface combined with a robust carcass construction results in a calibrated blanket thickness with a minimal relevance.

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**