


Key performance

- Suitable for high speed newspaper presses
- Positive paper feed
- Implements all benefits of the **Dynatech System**:
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Newspaper Coldset

Vulcan Editor 20 is available in 3 ply, 1,95 mm thickness.

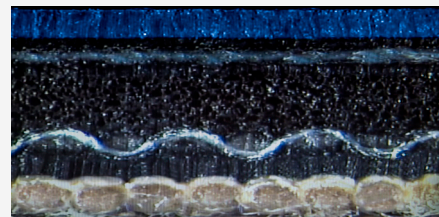

Vulcan Editor 20

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Positive
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
NEW TECHNOLOGY	Dynatech
ADDITIONAL INFORMATION	
APPLICATIONS	Special rubber compound used for the compressible layer

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**