

vulcan® Intaglio


Key performance

- Special fabric with extremely strong and low stretch resistance to guarantee stability and longevity on the press
- Surface able to allow a proper foil release and excellent ink transfer even at low mechanical pressure
- High temperature resistance, till 100 °C

MAIN APPLICATION

Security Printing

Vulcan Intaglio is available in 1 ply, 0,50 mm thickness.

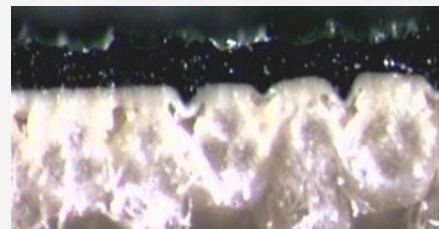

Vulcan Intaglio



The product at a glance

PRINTING SURFACE COLOUR	Black
THICKNESS (mm)	0,50 +0,04/-0,03
COMPRESSIBILITY	Not compressible
TABER ABRASION (WEIGHT 500g, WHEEL H22, 500 CYCLES)	≤7
ELONGATION (%)	≤8/ ≤20
TENSILE STRENGTHS (N/mm)	≥1400 / ≥250
ADDITIONAL INFORMATION	
APPLICATIONS	Printing of banknotes, checks, passports, visa, holograms

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**