




Key performance

- Improved reboundability and striking absorption
- Increased flexibility, easy handling and machine set up
- Improvement of half tone reproduction and overall print quality
- Enhanced smash resistance
- Increased blanket lifetime

MAIN APPLICATION

Commercial Sheetfed,
Packaging (paper & cardboard)

**Vulcan Combo Plus is available
in 3 ply, 1,95 mm thickness.**

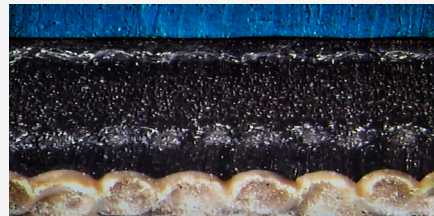

Vulcan Combo Plus

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Light blue
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,6
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>150
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
INK TRANSFER	Suitable for printing using both UV and conventional inks

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**