



vulcan® Folio UV


Key performance

- Specifically designed for UV inks
- Excellent half tone reproduction
- Reduced gauge loss
- Implements all benefits of the **Dynatech System:**
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Commercial Sheetfed

Vulcan Folio UV is available in 3-ply, 1.96 mm thickness.

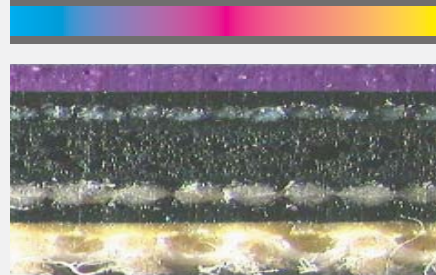

Vulcan Folio UV

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER SOLVENT PROTECTION	No
NEW TECHNOLOGY	Dynatech
ADDITIONAL INFORMATION	
TOP FACE COMPOUND	Dedicated for UV inks

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printing@trelleborg.com**