



# 544SB


## Key performance

- Ground smooth for sharp dots and cleaner print
- New improved surface promotes smoother ink transfer
- Quick release characteristics
- Hybrid capabilities.

## MAIN APPLICATION

High quality Sheetfed

**Printec 544SB is available in 4 ply,  
.077" thickness**

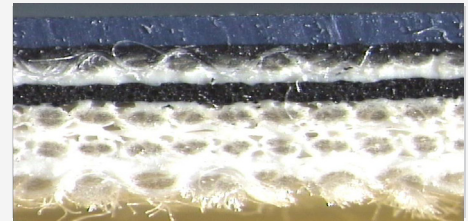

## The product at a glance

<b>INK COMPATIBILITY</b>	Conventional and Hybrid
<b>PRINTING SURFACE COLOUR</b>	Dark Blue
<b>NOMINAL THICKNESS (Inches)</b>	.0767" to .0783"
<b>RUPTURE STRENGTH</b>	58.0 Kgf/cm
<b>SURFACE ROUGHNESS (Ra micron)</b>	0.40 Ra
<b>ELONGATION (%)</b>	< 2.0%
<b>TENSILE STRENGTH (N/MM)</b>	Min. 60
<b>WATER &amp; SOLVENT PROTECTION</b>	No
<b>HARDNESS</b>	79 Shore A
<b>ADDITIONAL INFORMATION</b>	
<b>BLANKET CONSTRUCTION</b>	Compressible/closed cell

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**

[www.trelleborg.com/printing](http://www.trelleborg.com/printing)

The information contained in this document is intended to provide guidance. The information is NOT a specification and all figures in the document are nominal. This document and the information it contains do not create any warranties for any product and Trelleborg Printing Solutions disclaims any warranty of merchantability or fitness for a particular purpose for the product described in this document. This document discloses information that is proprietary to Trelleborg Printing Solutions. The receipt or possession of the document does not confer any right to reproduce or disclose the document, any information contained in it, or any physical article or device, or to practice any method or process except by written agreement with Trelleborg Printing Solutions. Trelleborg Printing Solutions is committed to the ongoing development of its products. For that reason, Trelleborg Printing Solutions reserves the right to alter the actual specifications of its products without prior notice.