



Printec[®] 211-Y


Key performance

- Sticky back blanket
- Very flexible and soft carcass for easy mounting
- High print quality
- Very versatile: suitable for labels & envelopes printing
- Adhesive: clean and easy removal from the cylinder

MAIN APPLICATION

Business Forms

Printec 211-Y is available in 1-ply, 0,90/0,95/1,00/1,05 mm thickness.

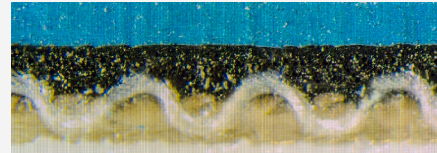

Printec 211-Y



The product at a glance

| | |
|--|--------------------------|
| INK COMPATIBILITY | Hybrid |
| THICKNESS (mm) | 0,90 - 0,95 - 1,00- 1,05 |
| PRINTING SURFACE COLOUR | Blue |
| AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation | 250 |
| SURFACE ROUGHNESS (Ra micron) | 0,8 |
| ADDITIONAL INFORMATION | |
| APPLICATIONS | Clean and easy removal |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**