



Printec 134


Key Performance

- Precisely ground and buffed quick release surface
- Unique, thicker compressible layer
- Conventional and Hybrid ink compatible
- Reduced piling and linting
- Uniform gauge
- Compressible construction
- Washes easily
- Defect-free surface

MAIN APPLICATION

Sheetfed, Packaging

**Printec 134 is available in 3 ply
1,98 mm thickness**

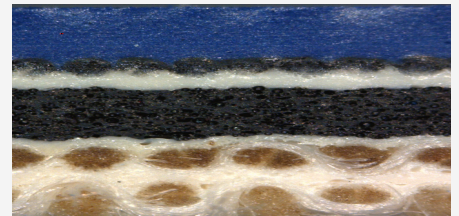

Printec 134



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Dark Blue
THICKNESS (mm)	1,98
SURFACE ROUGHNESS Ra (micron)	1.0
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	Improved ink release and cleaning

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**