



Printec 574




Key performance

- Specifically designed for a wide range of applications in sheetfed printing and large format packaging
- Suitable for high volumes printing
- Improved performance in tough printing conditions

MAIN APPLICATION

Commercial Sheetfed

Printec 574 is available in 4-ply, 1,95 mm thickness.

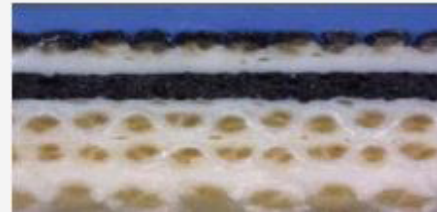

Printec 574



The product at a glance

INK COMPATIBILITY	Hybrid
THICKNESS (mm)	1.95
PRINTING SURFACE COLOUR	Blue
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
WATER AND SOLVENT PROTECTION	Yes

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**