



# Printec® 574-A




## Key performance

- Specifically designed for a wide range of applications in sheetfed printing and large format packaging
- Suitable for high volumes printing
- Improved performance in tough printing conditions

## MAIN APPLICATION

Commercial Sheetfed, Packaging

**Printec 574-A is available in 4-ply, 1,96 mm thickness.**

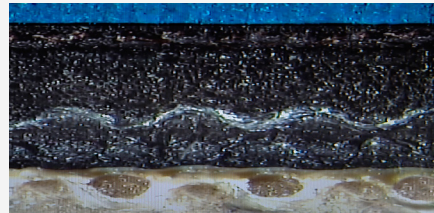

**Printec 574-A**



## The product at a glance

<b>INK COMPATIBILITY</b>	Conventional
<b>THICKNESS (mm)</b>	1.96 ± 0,02
<b>PRINTING SURFACE COLOUR</b>	Blue
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	260
<b>SURFACE ROUGHNESS (Ra micron)</b>	1,0
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTHS (N/mm)</b>	>70
<b>WATER &amp; SOLVENT PROTECTION</b>	No
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Commercial Sheetfed and Packaging

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**