


Key Performance

- Very good half tone reproduction and overall printing quality
- Proper shock mark absorption
- Excellent paper smash resistance
- Reliable commercial sheetfed performer

MAIN APPLICATION

Sheetfed, Packaging

Printec 865 is available in 1.96 mm thickness, 3 ply

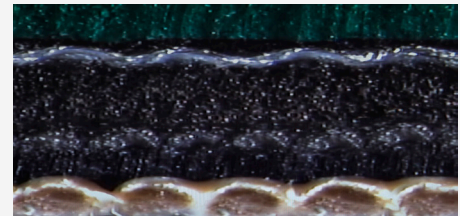

Printec 865

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Dark Green
THICKNESS (mm)	1.96
AVERAGE LOAD VALUE N/cm² @ 0,20 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,2
WATER & SOLVENT PROTECTION	No

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**