

# Rollin<sup>®</sup> Suntech


## Key performance

- Specifically designed for the latest UV applications (LE/HUV, LED UV)
- Excellent printing quality (solids and half tone reproduction)
- Very good ink release
- Avoid ink back-trapping
- Implements all benefits of the Dynatech System:
  - . Excellent smash and edge marks resistance
  - . Better vibration absorption

## MAIN APPLICATION

Commercial Sheeted

**Rollin Suntech is available in 1.96 mm thickness, 3-ply**

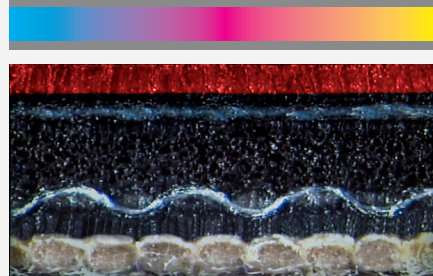

**Rollin Suntech**

## ✓ The product at a glance

|  |                      |
|--|----------------------|
| <b>INK COMPATIBILITY</b>   | UV                   |
| <b>PRINTING SURFACE COLOUR</b>                                       | Red                  |
| <b>THICKNESS (mm)</b>  | 1,96                 |
| <b>AVERAGE LOAD VALUE<br/>N/cm<sup>2</sup> @ 0,23 mm Indentation</b> | 250                  |
| <b>SURFACE ROUGHNESS<br/>(Ra micron)</b>                             | 0,8                  |
| <b>WATER &amp; SOLVENT PROTECTION</b>                                | No                   |
| <b>ADDITIONAL INFORMATION</b>  |                      |
| <b>APPLICATIONS</b>  | DYNATECH HUV, LED UV |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**