

Rollin[®] Suntech


Key performance

- Specifically designed for the latest UV applications (LE/HUV, LED UV)
- Excellent printing quality (solids and half tone reproduction)
- Very good ink release
- Avoid ink back-trapping
- Implements all benefits of the Dynatech System:
 - . Excellent smash and edge marks resistance
 - . Better vibration absorption

MAIN APPLICATION

Commercial Sheeted

Rollin Suntech is available in 1.96 mm thickness, 3-ply

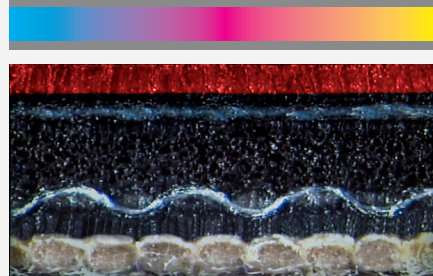

Rollin Suntech

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Red
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	DYNATECH HUV, LED UV

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**