

Rollin® Graffity Plus


Key performance

- Excellent half tone reproduction
- Reduced gauge loss
- Implements all benefits of the **Dynatech System:**
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Heatset

Rollin Graffity Plus is available in 3-ply, 1.95 mm thickness.

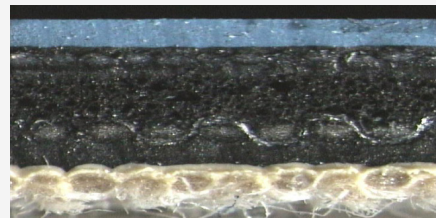

Rollin Graffity Plus



The product at a glance

| | |
|---|---|
| INK COMPATIBILITY | Hybrid |
| PRINTING SURFACE COLOUR | Blue |
| THICKNESS (mm) | 1,95 |
| AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation | 250 |
| SURFACE ROUGHNESS (Ra micron) | 0,6 |
| ELONGATION (%) | <0,9 |
| TENSILE STRENGTHS (N/mm) | >60 |
| WATER SOLVENT PROTECTION | Yes |
| NEW TECHNOLOGY | Dynatech |
| ADDITIONAL INFORMATION | |
| APPLICATION | Suitable also to be used for packaging printing |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**