

Rollin® UV-E




Key performance

- Specifically designed for UV applications
- Excellent half tone production
- Excellent smash resistance
- Suitable for packaging and metal decorating applications
- Sticky back blanket

MAIN APPLICATION

Commercial Sheetfed,
Packaging, Metal Decorating

**Rollin UV-E available in 3 ply,
1,71/1,96 mm thickness.**

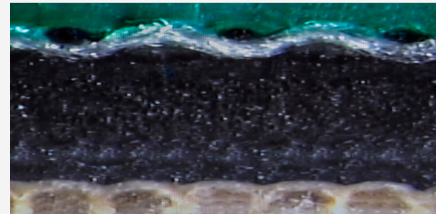

Rollin UV-E

✓ The product at a glance

| | |
|--|-----------------------------|
| INK COMPATIBILITY | UV |
| PRINTING SURFACE COLOUR | Green |
| THICKNESS (mm) | 1,71/1,96 |
| AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation | 250 |
| SURFACE ROUGHNESS (Ra micron) | 0,8 |
| WATER & SOLVENT PROTECTION | No |
| ADDITIONAL INFORMATION | |
| CARCASS CONSTRUCTION | High uv chemical resistance |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**