

# Rollin® UV-E




## Key performance

- Specifically designed for UV applications
- Excellent half tone production
- Excellent smash resistance
- Suitable for packaging and metal decorating applications
- Sticky back blanket

## MAIN APPLICATION

Commercial Sheetfed,  
Packaging, Metal Decorating

**Rollin UV-E available in 3 ply,  
1,71/1,96 mm thickness.**

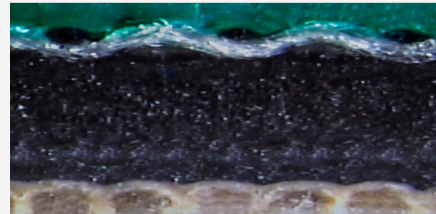

Rollin UV-E

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	UV
<b>PRINTING SURFACE COLOUR</b>	Green
<b>THICKNESS (mm)</b>	1,71/1,96
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	250
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>WATER &amp; SOLVENT PROTECTION</b>	No
<b>ADDITIONAL INFORMATION</b>	
<b>CARCASS CONSTRUCTION</b>	High uv chemical resistance

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**