



Rollin[®] Metal UV


Key performance

- Ideal for UV multi-colour presses
- Excellent half tone reproduction and ink transfer coverage
- Extreme quick release
- High UV chemical resistance

MAIN APPLICATION

UV

Rollin Metal UV available in 3 ply, 1,96 mm thickness.

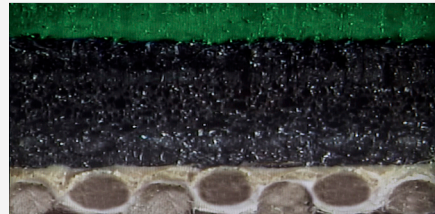

Rollin Metal UV



The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	400
SURFACE ROUGHNESS (Ra micron)	0,8
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	Packaging and metal decorating

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**