



Rollin[®] MPR40


Key performance

- Improved reboundability and striking absorption
- Increased flexibility, easy handling and machine set up
- Improvement of half tone reproduction and overall print quality
- Enhanced smash resistance
- Increased blanket lifetime

MAIN APPLICATION

Commercial Sheetfed

Rollin MPR40 is available in 3 ply, 1,95 mm thickness

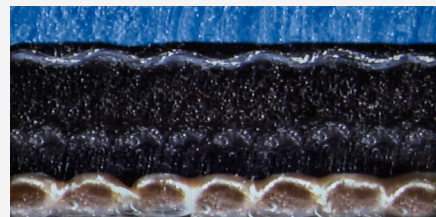

Rollin MPR40

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Light blue
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	245
SURFACE ROUGHNESS (Ra micron)	0,6
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>60

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**