

Rollin[®] Infinity Plus


Key performance

- Very good half tone reproduction and overall printing quality
- Proper shock mark absorption
- Excellent paper smash resistance
- Reliable commercial sheetfed performer

MAIN APPLICATION

Sheetfed, Packaging

Rollin Infinity Plus is available in 3-ply, 1,95mm thickness.

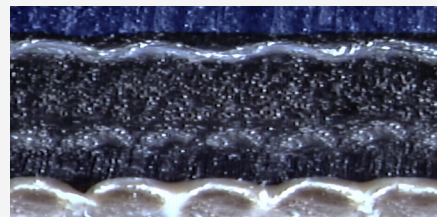

Rollin Infinity Plus

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,2
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	All-round sheetfed blanket.

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**