



Rollin[®]Wish




Key performance

- Suitable for hybrid printing with both UV and conventional inks
- Increased durability thanks to the top surface strong chemical resistance
- Increased blanket lifetime to maximize the cost per copy
- Sharp half tone for high quality requirements

MAIN APPLICATION

Commercial Sheetfed,
Packaging (paper & cardboard)

**Rollin Wish is available in 4 ply,
1,96 mm thickness.**

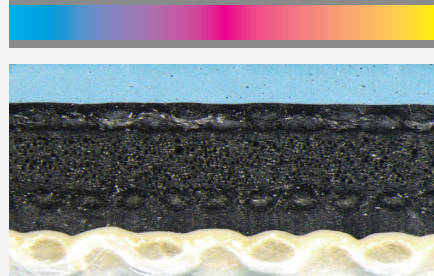

Rollin Wish



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Light blue
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,6
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
INK TRANSFER	Suitable for printing using both UV and conventional inks

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**