

vulcan[®] Royal Form UV


Key performance

- Specifically designed for UV inks
- Sticky back blanket
- High print quality
- High edge marking resistance
- Increased blanket lifetime
- Suitable for labels and envelopes printing
- Adhesive: clean and easy removal from the cylinder

MAIN APPLICATION

Business Forms, Labels

Vulcan Royal Form UV is available in 2 ply, 0,90 - 0,95 - 1,00 - 1,05 mm thickness.

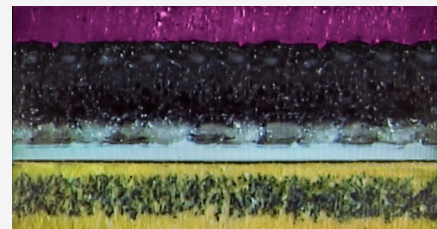

Vulcan Royal Form UV

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	0,90 - 0,95 - 1,00 - 1,05
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	300
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	N/A
TENSILE STRENGTHS (N/mm)	N/A
WATER & SOLVENT PROTECTION	N/A
ADDITIONAL INFORMATION	
APPLICATIONS	Dedicated for UV inks

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**