

vulcan[®] UV


Key performance

- Specifically designed for UV applications
- Increased blanket lifetime
- Reduced downtime due to less blanket changes
- Sticky back blanket is available for business forms and labels printing

MAIN APPLICATION

UV

Vulcan UV is available in 3 ply, 1,75 - 1,95 mm thickness.

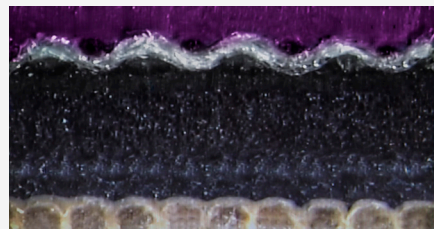

Vulcan UV

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	1,75 / 1,95
AVERAGE LOAD VALUE N/cm ² @ 0,23 mm Indentation	300
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	N/A
ADDITIONAL INFORMATION	
APPLICATIONS	Adhesive on Request

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**