

vulcan® Editor 10


Key performance

- Neutral paper feed
- Implements all benefits of the **Dynatech System**: better vibration absorption, less gears streaking marks, higher paper smash resistance, blanket consistency and excellent reboundability
- Designed with **Feed-O Technology**:
 - Optimum paper feed tension
 - Reduced risks of paper breaks
 - Easier control of colour register during the start-up
 - Improved paper wastage control

MAIN APPLICATION

Newspaper Coldset

Vulcan Editor 10 is available in
3 ply, 1,95 mm thickness

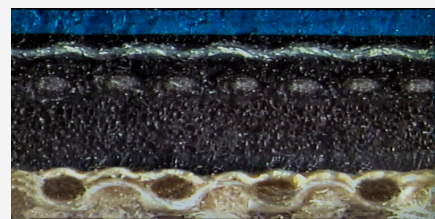

Vulcan Editor 10

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS(mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Neutral
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>67
WATER & SOLVENT PROTECTION	Yes
ADVANCED TECHNOLOGY	Dynatech and Feed-O
ADDITIONAL INFORMATION	
APPLICATIONS	Suitable for high speed presses
MORE VERSIONS	No Pack version available on demand

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**